


The Timken Company

4500 Mt Pleasant St. NW

N. Canton, OH 44720

Phone: (234) 262-3000

E-Mail: CustomerCAD@timken.com • **Web site:** www.timken.com

Part Number 619/6-2RS, Miniature Ball Bearings (600, 610, 620, 630)

Timken's deep groove ball bearings deliver reliable performance in a wide range of applications and conditions. With super-finished raceways and controlled geometries, our premium design helps ensure consistent quality.



[Specifications](#) | [Dimensions](#) | [Basic Load Ratings](#) | [Factors](#)

Specifications

Bore Size d	6 mm
Features	Contact Seals
Bearing Type	Standard DGBB

Dimensions

Outside Diameter D	15.000 mm
Outside Ring Width B	5 mm
Radius Rs min	0.2 mm



Basic Load Ratings


Cr - Dynamic Load Rating	1300 N
---------------------------------	--------

C0r - Static Load Rating	520 N
---------------------------------	-------

Factors

Grease Limiting Speed	46000 rpm
------------------------------	-----------

Oil Limiting Speed	54000 rpm
---------------------------	-----------

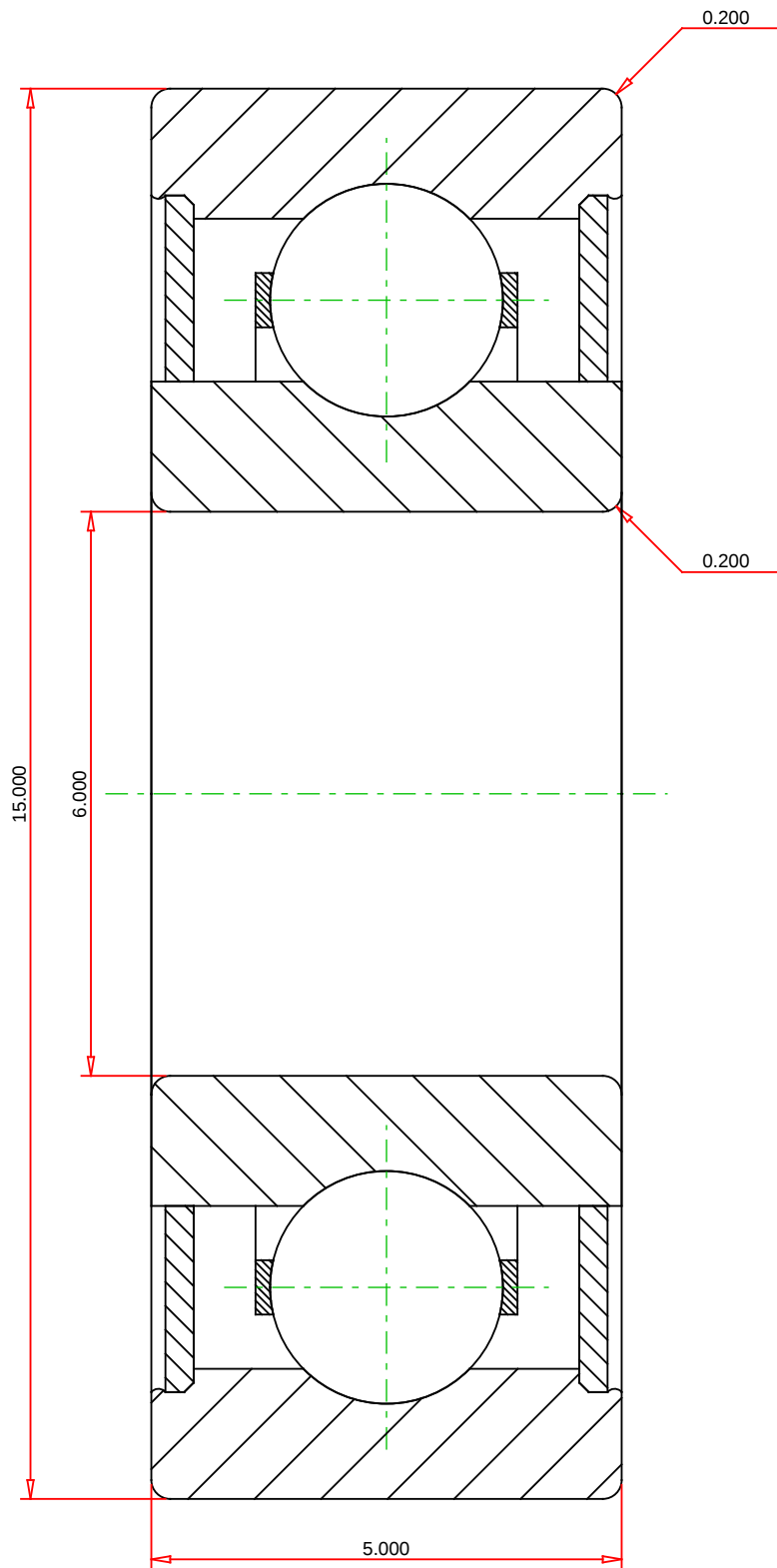

METRIC UNITS

Weight 0.004 kg

TIMKEN®

THE TIMKEN COMPANY
NORTH CANTON, OHIO USA

619/6-2RS
Miniature Ball Bearings (600, 610, 620, 630)

Dynamic Load Rating	1300	N
Static Load Rating	520	N

Every reasonable effort has been made to ensure the accuracy of the information contained in this writing, but no liability is accepted for errors, omissions or for any other reason.

FOR DISCUSSION ONLY