



The Timken Company
4500 Mt Pleasant St. NW
N. Canton, OH 44720
Phone: (234) 262-3000
E-Mail: CustomerCAD@timken.com • **Web site:** www.timken.com


Part Number 6007-2RS, Deep Groove Ball Bearings (6000, 6200, 6300, 6400)

Timken’s deep groove ball bearings deliver reliable performance in a wide range of applications and conditions. With super-finished raceways and controlled geometries, our premium design helps ensure consistent quality.



[Specifications](#) | [Dimensions](#) | [Basic Load Ratings](#) | [Factors](#)

Specifications	
Clearance	C0 (Normal)
Bore Size d	35 mm
Features	Contact Seals
Bearing Type	Standard DGBB

Dimensions	
Outside Diameter D	62 mm
Outside Ring Width B	14 mm
 Radius Rs min	1 mm

Basic Load Ratings



Cr - Dynamic Load Rating	15900 N
---------------------------------	---------


C0r - Static Load Rating	10300 N
---------------------------------	---------

Factors



Grease Reference Speed	11000 rpm
-------------------------------	-----------

Oil Reference Speed	16000 rpm
----------------------------	-----------

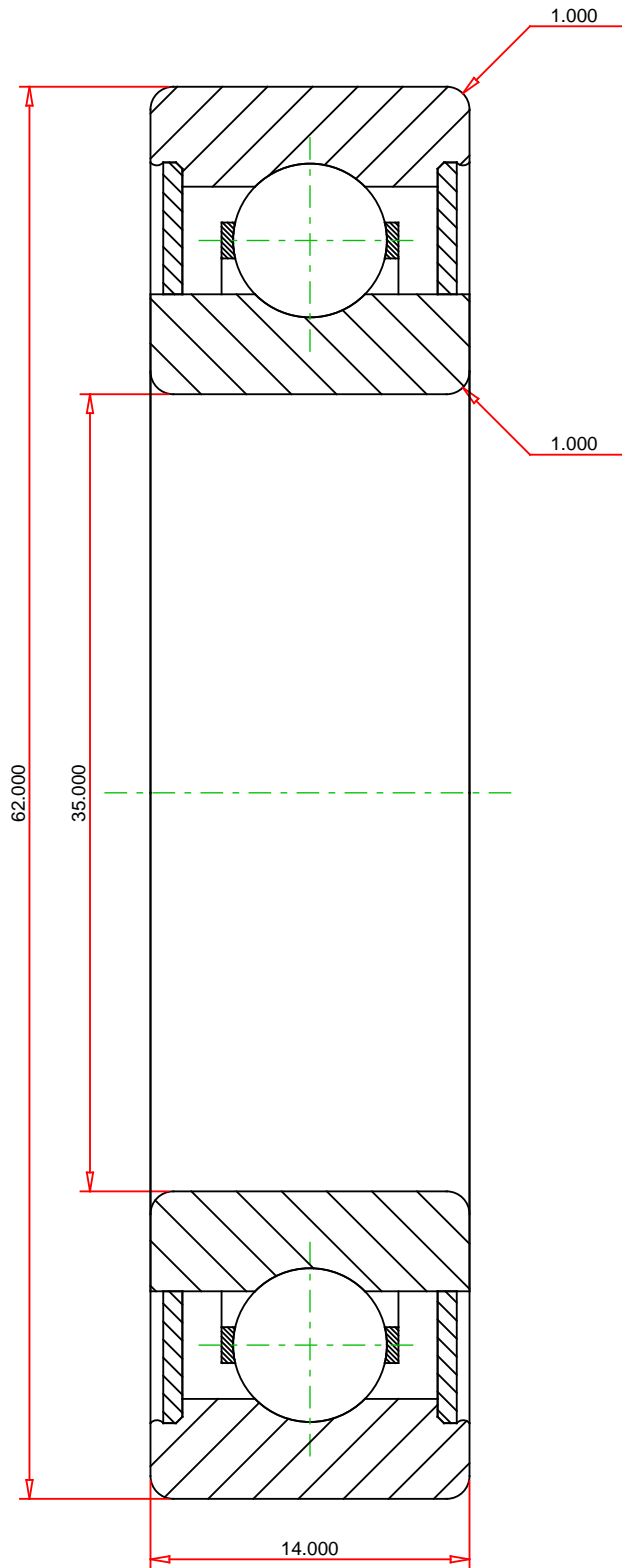

METRIC UNITS

Weight	0.15 kg	TIMKEN ®
		THE TIMKEN COMPANY NORTH CANTON, OHIO USA

6007-2RS Deep Groove Ball Bearings (6000, 6200, 6300, 6400)		
Dynamic Load Rating	15900	N
Static Load Rating	10300	N

Every reasonable effort has been made to ensure the accuracy of the information contained in this writing, but no liability is accepted for errors, omissions or for any other reason.

FOR DISCUSSION ONLY