


**The Timken Company**

4500 Mt Pleasant St. NW

N. Canton, OH 44720

**Phone:** (234) 262-3000

**E-Mail:** [CustomerCAD@timken.com](mailto:CustomerCAD@timken.com) • **Web site:** [www.timken.com](http://www.timken.com)

## Part Number 6008-2RS-C3, Deep Groove Ball Bearings (6000, 6200, 6300, 6400)

Timken's deep groove ball bearings deliver reliable performance in a wide range of applications and conditions. With super-finished raceways and controlled geometries, our premium design helps ensure consistent quality.



[Specifications](#) | [Dimensions](#) | [Basic Load Ratings](#) | [Factors](#)

### Specifications

<b>Clearance</b>	C3
<b>Bore Size d</b>	40 mm
<b>Features</b>	Contact Seals
<b>Bearing Type</b>	Standard DGBB

### Dimensions

<b>Outside Diameter D</b>	68 mm
<b>Outside Ring Width B</b>	15 mm
<b>Radius Rs min</b>	1 mm



## Basic Load Ratings



Cr - Dynamic Load Rating	16800 N
--------------------------	---------


C0r - Static Load Rating	11500 N
--------------------------	---------

## Factors



Grease Reference Speed	10000 rpm
------------------------	-----------

Oil Reference Speed	15000 rpm
---------------------	-----------

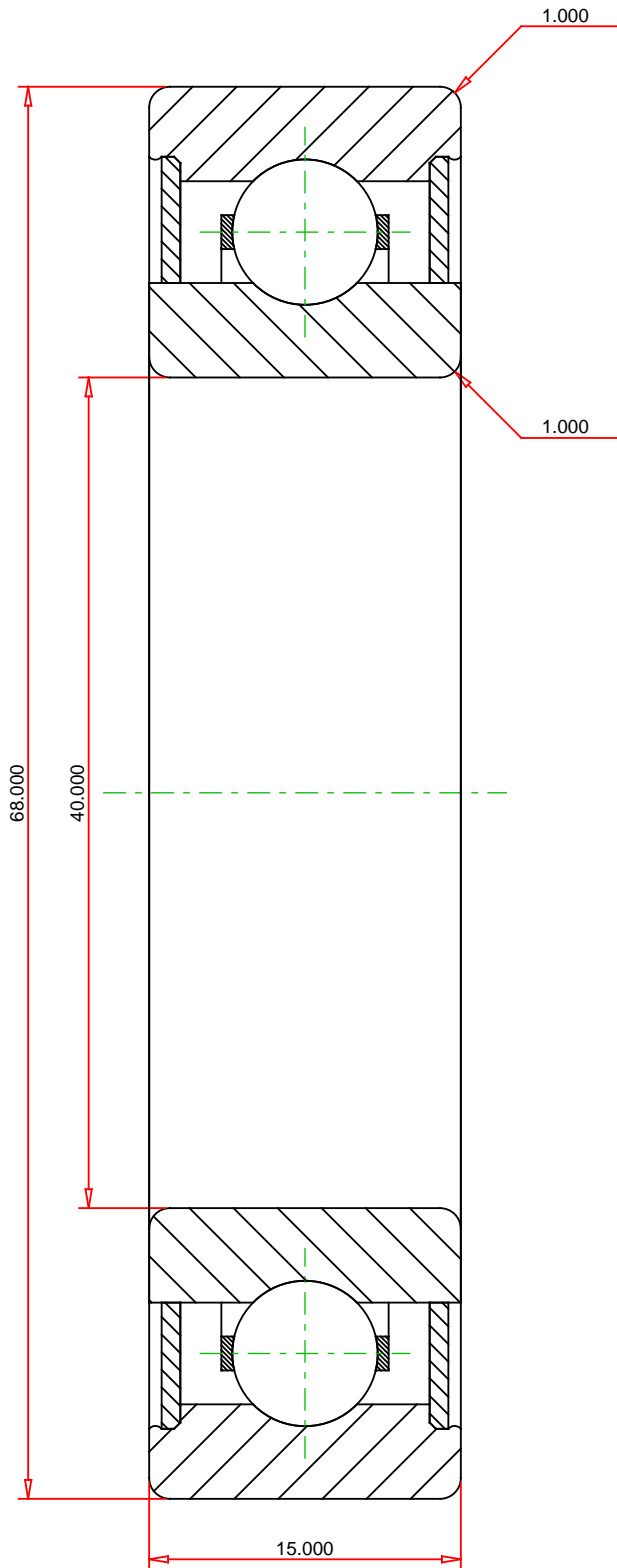

METRIC UNITS

Weight	0.19 kg	<div>TIMKEN®</div>	6008-2RS-C3 Deep Groove Ball Bearings (6000, 6200, 6300, 6400)	
		<div>THE TIMKEN COMPANY NORTH CANTON, OHIO USA</div>	<div>Dynamic Load Rating16800 N</div> <div>Static Load Rating11500 N</div>	

Every reasonable effort has been made to ensure the accuracy of the information contained in this writing, but no liability is accepted for errors, omissions or for any other reason.

FOR DISCUSSION ONLY