


The Timken Company

4500 Mt Pleasant St. NW

N. Canton, OH 44720

Phone: (234) 262-3000

E-Mail: CustomerCAD@timken.com • **Web site:** www.timken.com
Part Number 6026-NR-C3, Deep Groove Ball Bearings (6000, 6200, 6300, 6400)

Timken's deep groove ball bearings deliver reliable performance in a wide range of applications and conditions. With super-finished raceways and controlled geometries, our premium design helps ensure consistent quality.



[Key Dimensions](#) | [Dimensions](#) | [Basic Load Ratings](#) | [Factors](#)

Key Dimensions

Clearance	C3
Bore Size d	130 mm
Features	Snap Ring
Bearing Type	Standard DGBB

Dimensions

Outside Diameter D	200 mm
Outside Ring Width B	33 mm
Radius Rs min	2 mm



Snap Ring Diameter D2 max	212.900 mm
----------------------------------	------------

Snap Ring Width f max	3.100 mm
------------------------------	----------

Basic Load Ratings


Cr - Dynamic Load Rating	105000 N
---------------------------------	----------

C0r - Static Load Rating	96800 N
---------------------------------	---------

Factors

Grease Reference Speed	4100 rpm
-------------------------------	----------

Oil Reference Speed	5900 rpm
----------------------------	----------

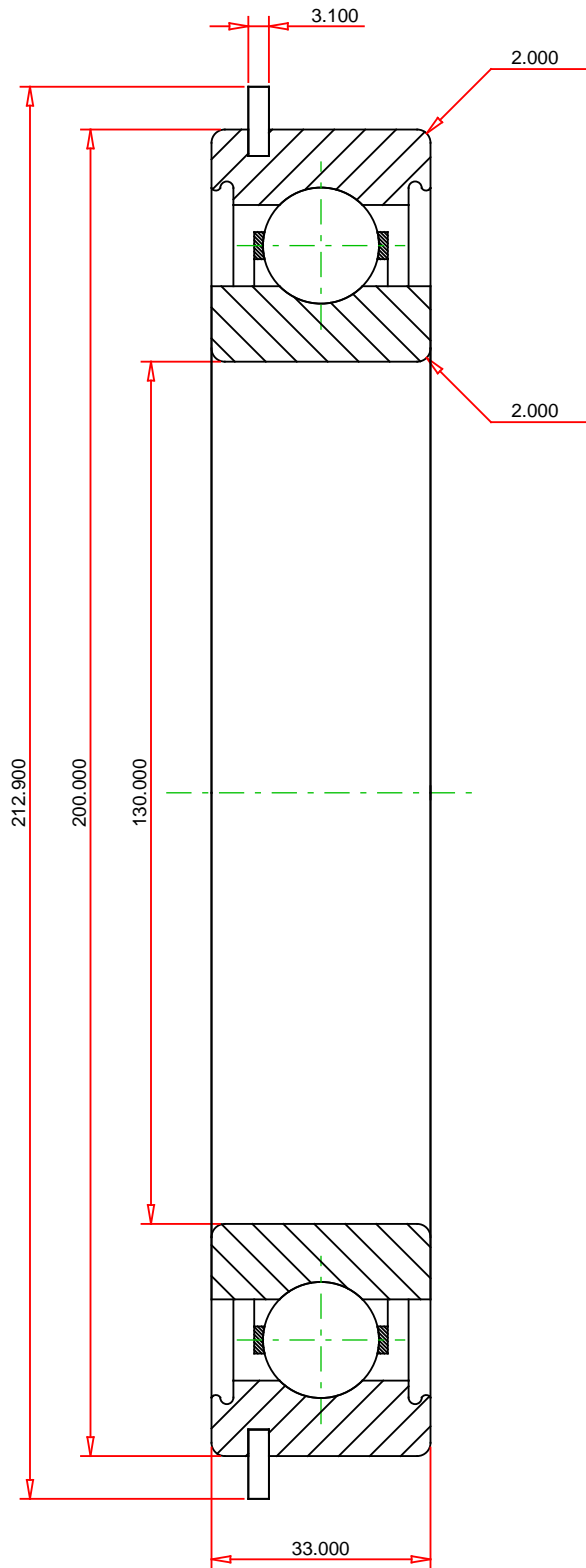

METRIC UNITS

Weight 3.15 kg

TIMKEN[®]

THE TIMKEN COMPANY
NORTH CANTON, OHIO USA

6026-NR-C3
Deep Groove Ball Bearings (6000, 6200, 6300, 6400)

Dynamic Load Rating 105000 N
Static Load Rating 96800 N

Every reasonable effort has been made to ensure the accuracy of the information contained in this writing, but no liability is accepted for errors, omissions or for any other reason.

FOR DISCUSSION ONLY