


The Timken Company

4500 Mt Pleasant St. NW

N. Canton, OH 44720

Phone: (234) 262-3000

E-Mail: CustomerCAD@timken.com • **Web site:** www.timken.com

Part Number 6202-2RS, Deep Groove Ball Bearings (6000, 6200, 6300, 6400)

Timken's deep groove ball bearings deliver reliable performance in a wide range of applications and conditions. With super-finished raceways and controlled geometries, our premium design helps ensure consistent quality.



[Specifications](#) | [Dimensions](#) | [Basic Load Ratings](#) | [Factors](#)

Specifications

Clearance	C0 (Normal)
Bore Size d	15 mm
Features	Contact Seals
Bearing Type	Standard DGBB

Dimensions

Outside Diameter D	35 mm
Outside Ring Width B	11 mm
Radius Rs min	0.6 mm



Basic Load Ratings


Cr - Dynamic Load Rating7600 N

C0r - Static Load Rating3700 N

Factors

Grease Reference Speed19000 rpm

Oil Reference Speed28000 rpm

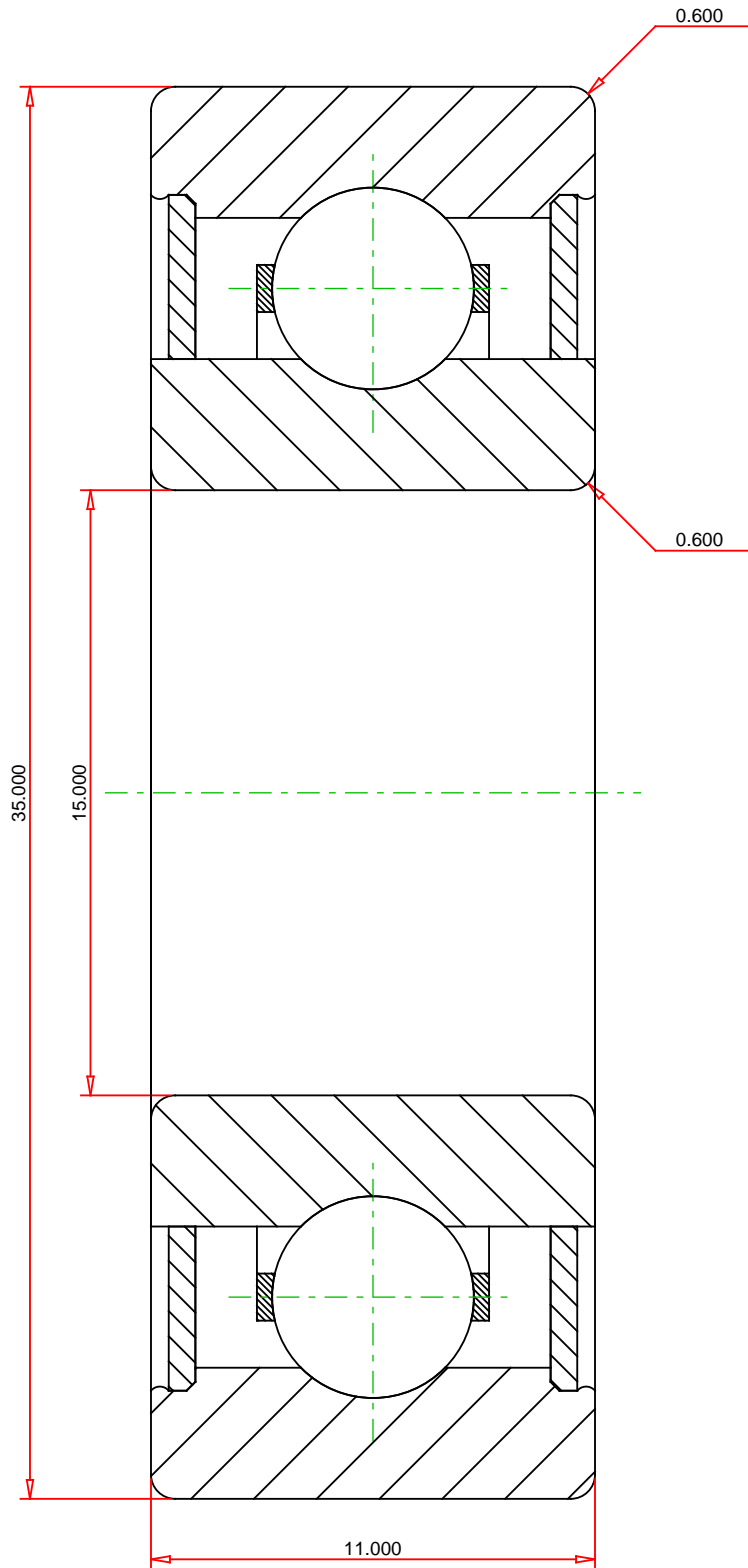

METRIC UNITS

Weight 0.05 kg

TIMKEN®

THE TIMKEN COMPANY
NORTH CANTON, OHIO USA

6202-2RS
Deep Groove Ball Bearings (6000, 6200, 6300, 6400)

Dynamic Load Rating 7600 N
Static Load Rating 3700 N

Every reasonable effort has been made to ensure the accuracy of the information contained in this writing, but no liability is accepted for errors, omissions or for any other reason.

FOR DISCUSSION ONLY