



The Timken Company

4500 Mt Pleasant St. NW

N. Canton, OH 44720


Phone: (234) 262-3000

E-Mail: CustomerCAD@timken.com • **Web site:** www.timken.com

Part Number RA012RR, Fafnir® Eccentric Locking Collar Ball Bearings



RA-RR, RA-RRB Standard Series

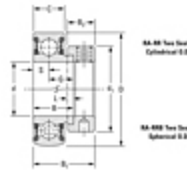

[Specifications](#) | [Dimensions](#) | [Basic Load Ratings](#)

Specifications


Series	Standard
Shaft Size d	3/4 in
Bore Type	Cylindrical bore
Bearing Type	Ball Bearing
Material	Bearing Steel
Lubrication Type	Non-Relubricatable
O.D. Type	Cylindrical OD
Sub Series	RA..RR
Seal Type	Molded Shroud

Dimensions

Outside Diameter D	1.85 in 47 mm
Inner Ring Width B	0.844 in 21.44 mm
Outside Ring Width C	0.591 in 15 mm
Radius r	0.024 in 0.6 mm
Center of Bearing from End S	0.295 in 7.49 mm
Set Screw Size	1/4-20
Number of Set Screws	2
Angle between Set Screws	90 °
Dimension d1	1.311 in 33.3 mm
Dimension B1	1.22 in 31 mm
Dimension B2	0.531 in 13.5 mm

Basic Load Ratings

Static Load Rating	1460 lbf 6500 N
Dynamic Load Rating	3190 lbf 14200 N

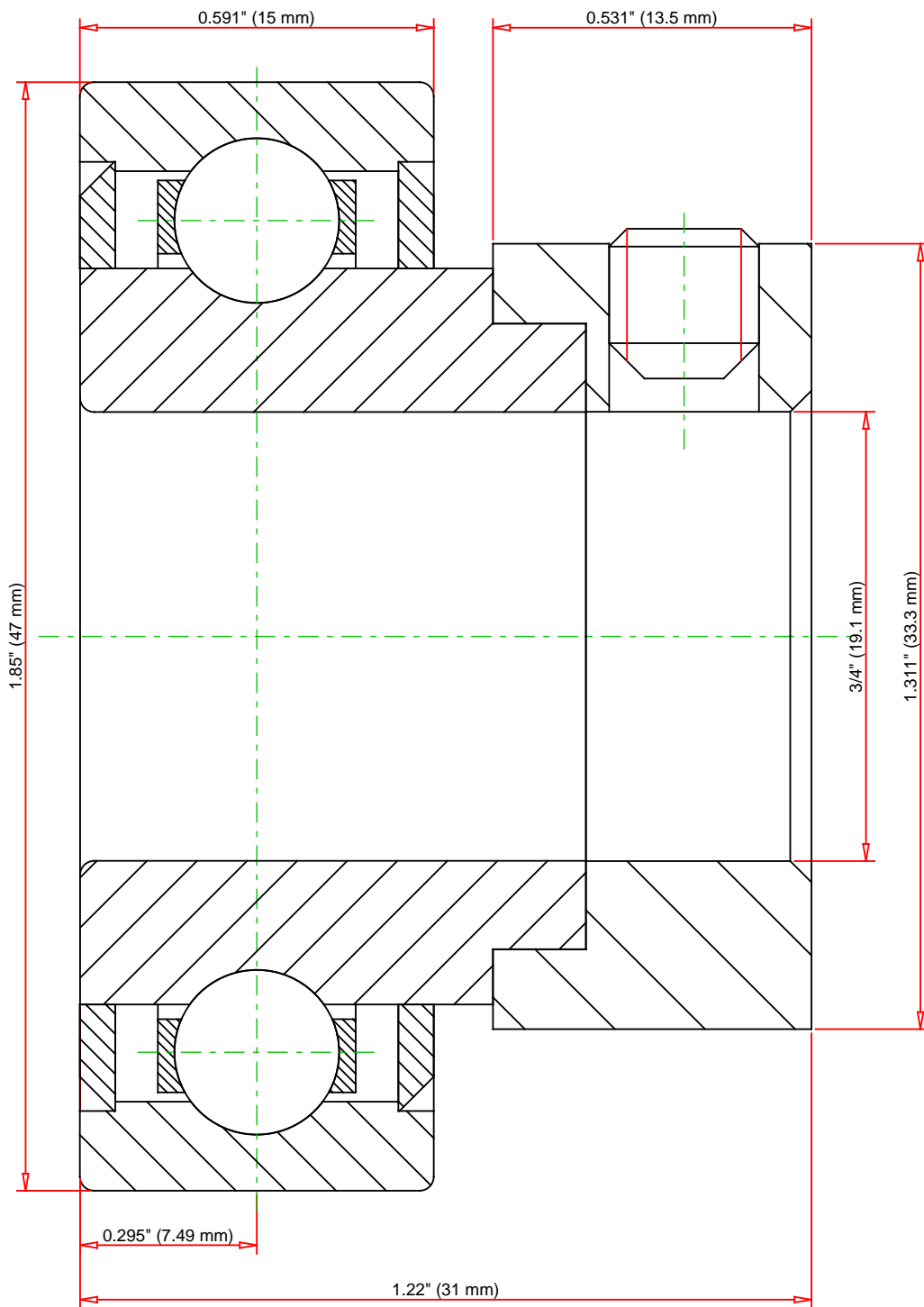

Weight	0.5 lb	0.2 kg	<div>TIMKEN®</div> <div>THE TIMKEN COMPANY</div> <div>NORTH CANTON, OHIO USA</div>	RA012RR		
				Fafnir® Eccentric Locking Collar Ball Bearings		
				Static Load Rating	1460 lbf	6500 N
				Dynamic Load Rating	3190 lbf	14200 N
Every reasonable effort has been made to ensure the accuracy of the information contained in this writing, but no liability is accepted for errors, omissions or for any other reason.				FOR DISCUSSION ONLY		